

15.5 [394]





#### MAINTENANCE OF UPS

- CAUTION** - RISK OF ELECTRIC SHOCK. DO NOT REMOVE COVER UNLESS YOU ARE QUALIFIED TO DO SO. ONLY QUALIFIED PERSONNEL.
- CAUTION** - RISK OF ELECTRIC SHOCK. THIS UPS RECEIVES POWER FROM MORE THAN ONE SOURCE - DISCONNECTOR OF THE AC SOURCES IS REQUIRED TO SERVICIZE THIS UNIT BEFORE SERVICING.
- CAUTION** - FOR USE IN A CONTROLLED ENVIRONMENT. REFER TO MANUAL FOR ENVIRONMENTAL CONDITIONS.
- CAUTION** - SEE INSTALLATION INSTRUCTIONS BEFORE CONNECTION TO THE SUPPLY.

#### INSTALLATION OF UPS

- 1.) ENSURE MAINTENANCE BYPASS SWITCH IS ILLUMINATED.
- 2.) SWITCH TO MAINTENANCE BYPASS POSITION. (LOAD IS NOW UNPROTECTED)
- 3.) ENSURE UPS LAMP IS ILLUMINATED.
- 4.) SWITCH TO UPS POSITION. (LOAD IS NOW PROTECTED BY UPS)

5.24 [132]

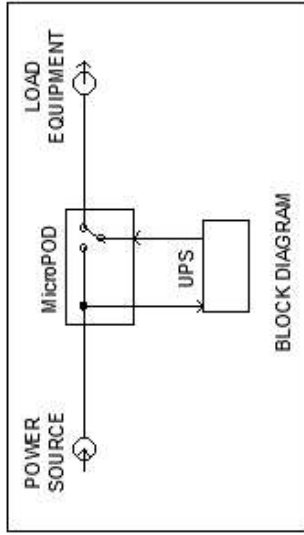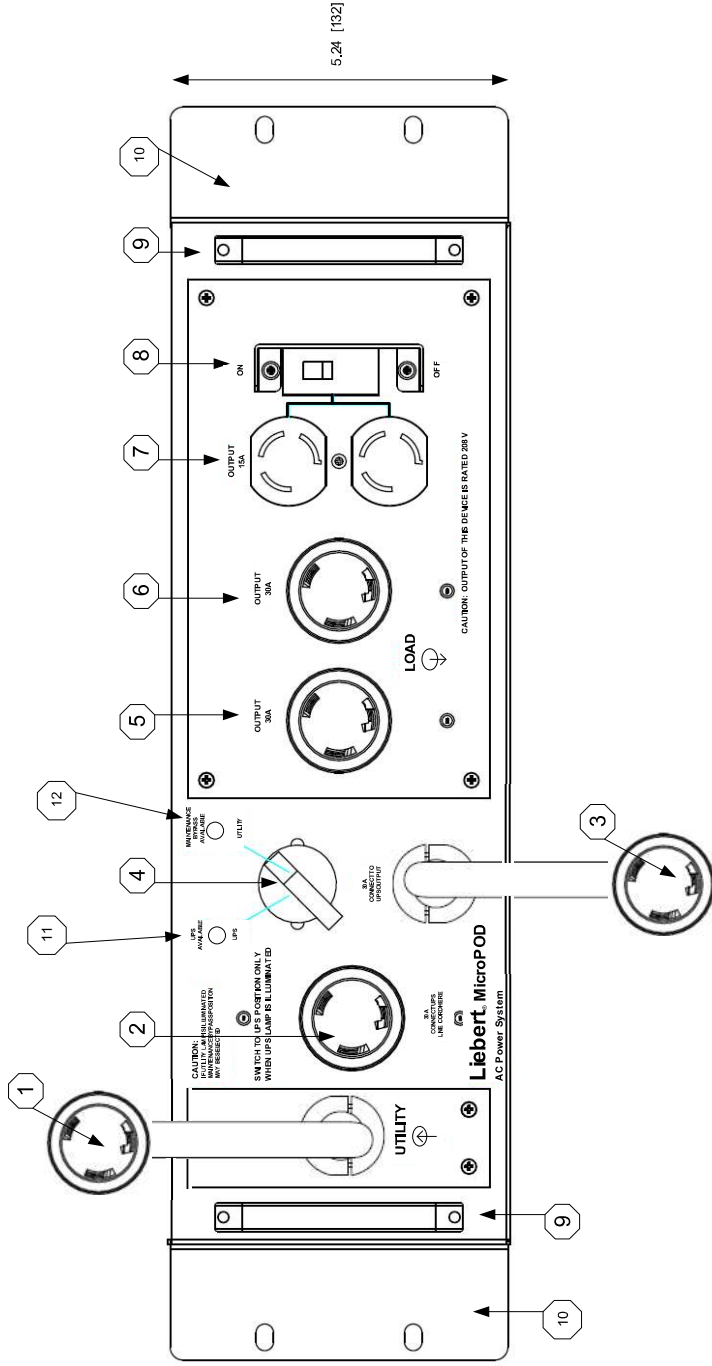

BLOCK DIAGRAM

#### NOTES:

1. INSTALLATION MUST BE IN ACCORDANCE WITH NATIONAL AND LOCAL ELECTRICAL CODES.
2. ALL DIMENSIONS ARE IN INCHES [mm]
3. UNIT DIMENSIONS:  
15.5" W x 5.24" D x 5.24" H [394mm x 132mm x 132mm]
4. UNIT WEIGHT: 7 lbs [3.2 kg]
5. SHIPPING DIMENSIONS:  
15.5" W x 5.24" D x 5.24" H [394mm x 132mm x 132mm]
6. SHIPPING WEIGHT: 9 lbs [4.1 kg]

#### LEGEND:

- 1 UTILITY INPUT CORD, 10 FT, NEMA L6-30P
- 2 UPS INPUT RECEPTACLE, NEMA L6-30R
- 3 UPS OUTPUT CORD, 6 FT, NEMA L6-30P
- 4 ROTARY BYPASS SWITCH
- 5 OUTPUT RECEPTACLE, NEMA L6-30R
- 6 OUTPUT RECEPTACLE, NEMA L6-30R
- 7 OUTPUT RECEPTACLES, NEMA L6-15R2
- 8 OUTPUT CIRCUIT BREAKER FOR #7, 15A, 2 POLE
- 9 RACKMOUNT HANDLES
- 10 RACKMOUNT BRACKETS
- 11 UPS AVAILABLE INDICATOR LAMP
- 12 INPUT/BYPASS SOURCE INDICATOR LAMP

SHEET NO.

1 OF 1

DRAWN BY:

J FUCHIK

TITLE

MICROPOD - GXT5-03POD01

MAINTENANCE BYPASS WITH

(2) L6-30R AND (2) L6-15R OUTPUT RECEPTACLES

DWG NO.

GXT5-03KPOD01

DATE: (LATEST REV)

25-JAN-2021

REVISION

0

1050 Dearborn Drive

PO Box 29186

Columbus, OH 43085

