


Disclosure and photocopying of this document, exploitation and communication of its contents are not permitted, unless permission is expressly granted. All rights are reserved.

FRONT VIEW

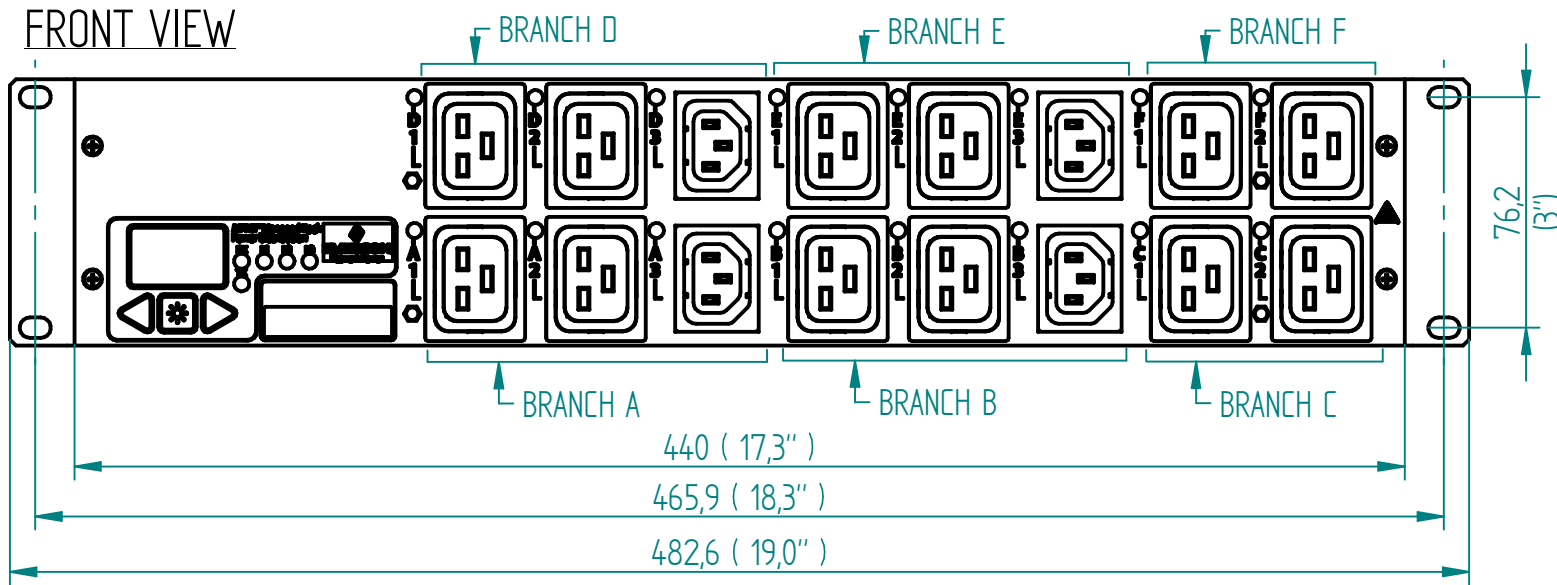


OUTPUT POWER

BRANCH	PHASE	RECEPTACLE TYPE (QUANTITY)	VOLTAGE (V)	MAX. CONTINUOUS AMPS (A)	
				PER RECEPTACLE	PER BRANCH
A	L1-L2	1xC13, 2xC19	200-240	12/16	16
B	L2-L3	1xC13, 2xC19	200-240	12/16	16
C	L3-L1	2xC19	200-240	16	16
D	L1-L2	1xC13, 2xC19	200-240	12/16	16
E	L2-L3	1xC13, 2xC19	200-240	12/16	16
F	L3-L1	2xC19	200-240	16	16

METERING PARAMETER	MEASUREMENT ACCURACY
VOLTAGE	±1 % + 0.1 VAC
CURRENT	±1.5 % + 0.01 A FROM 1 % TO 10 % OF UNIT RATING; ±1 % FROM >10 % TO 125 % OF UNIT RATING



REAR VIEW

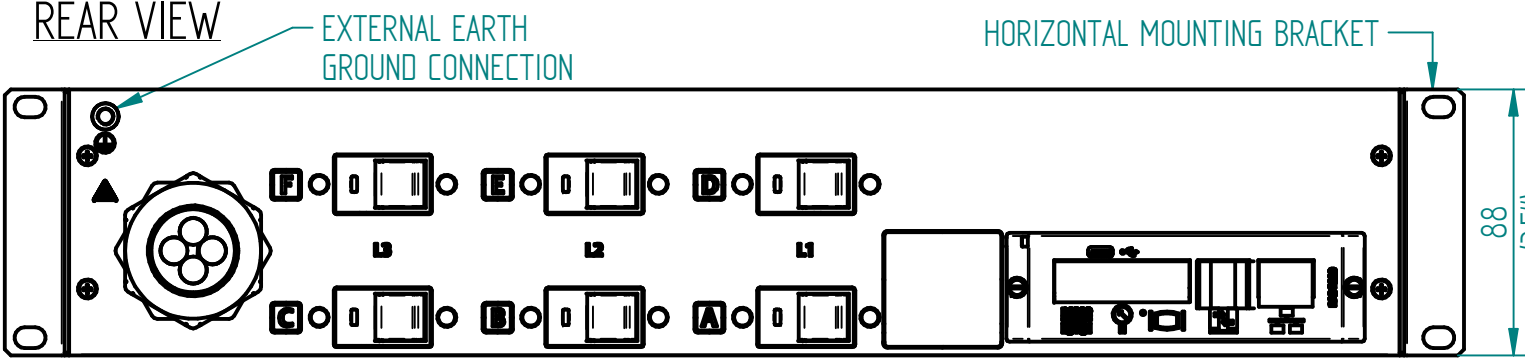

INPUT POWER

INPUT CORD	INPUT PLUG	WIRE COUNT	FREQUENCY (Hz)	VOLTAGE (V)	RATED AMPS (A)	MAX. CONT. AMPS (A)
10 ft / 3 m	IEC 60309	3/PE	50/60	200-240	60	48

UPPER VIEW

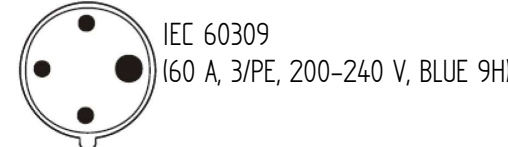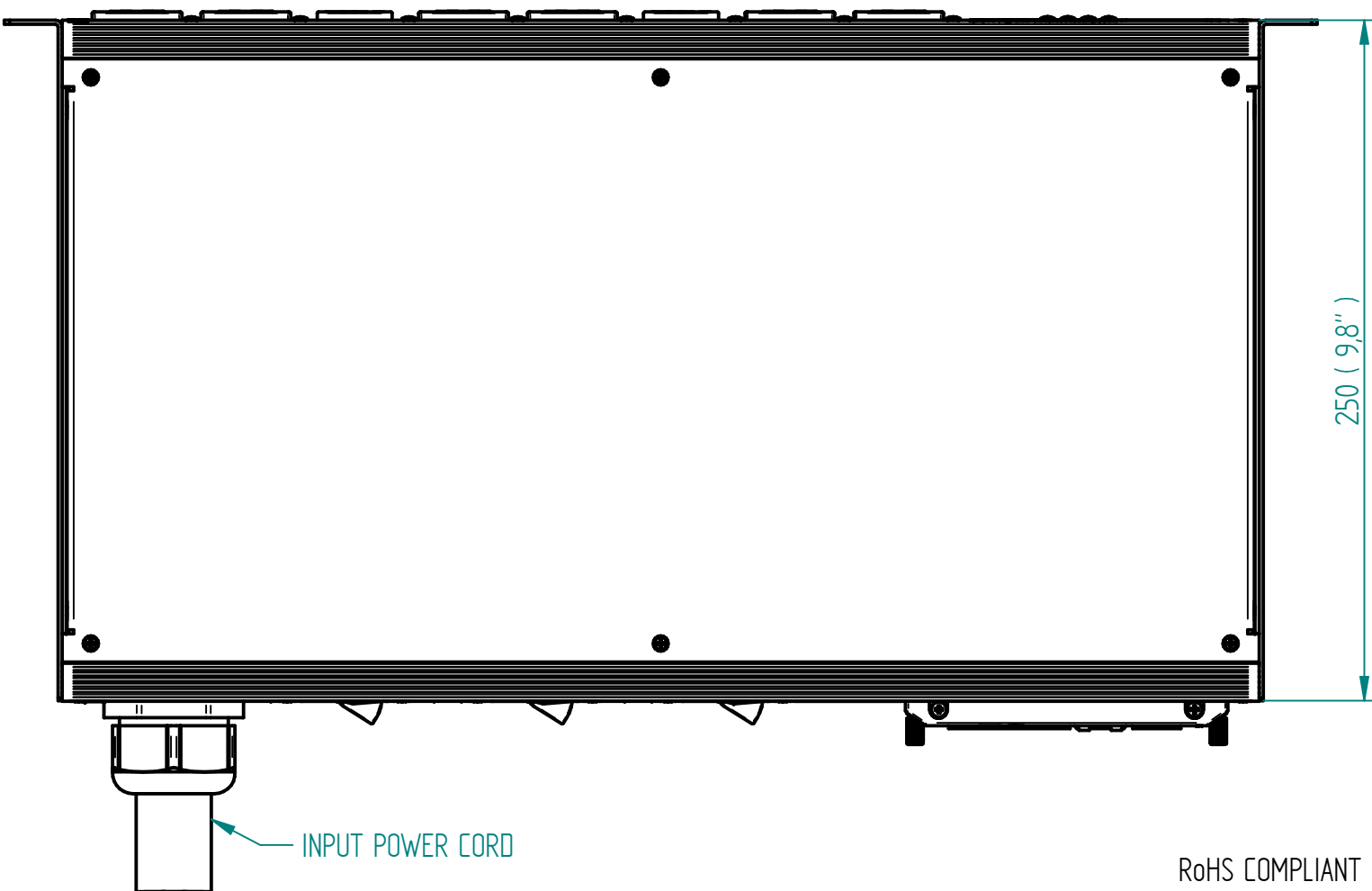

AGENCY COMPLIANCE:

- UL certification: UL 60950-1 (2nd), CSA C22.2 No. 60950-1-07
- FCC certification
- CB certification: IEC 60950-1 (2nd)

ENVIRONMENTAL RATING:

OPERATING TEMPERATURE: 5 °C - 60 °C (41 °F - 140 °F) NON-CONDENSING, NON-CORROSIVE, 10 % - 90 % RH
 STORAGE TEMPERATURE: -20 °C - 85 °C (-4 °F - 185 °F)
 MAX. OPERATING ALTITUDE: 2000 m

NOTES:

- UNIT DIMENSIONS: 440 mm (17.3") W x 250 mm (9.8") D x 88 mm (3.5") H
- UNIT WEIGHT: 8 kg / 17,6 lbs
- SHIPPING DIMENSIONS: 543 mm (21.4") W x 485 mm (19.1") D x 240 mm (9.5") H
- SHIPPING WEIGHT: 8,5 kg / 18,7 lbs
- (2) MOUNTING BRACKETS SUPPLIED WITH EACH UNIT. BOTH SIDES CAN BE USED TO MOUNT THE PDU.

 Dimensions in mm	Allgemeintoleranzen General tolerances		Oberfläche Finish	Werkstoff / Material	Gewicht: Weight: -
	-		-	-	-
	Drawn	04/05/16	Name	Bezeichnung / Description	
	Checked	04/05/16	Racek	MPH2-NRC_3P4W-60A_4N-12O	
	Approved	-	Votýpka	Input and Branch Metered + Outlet Metered/Switched	
				Zeichnungs-Nr. / Drawing no.	Maßstab Scale
				MPHR6325	
Rev.	Change	Date	Name	Verwendet in / Used in	Blatt/Sheet
B	18154	13.06.2017	Petrů	-	1/1

RoHS COMPLIANT

Weitergabe sowie Vervielfältigung dieser Unterlage, Verwertung und Mitteilung ihres Inhalts nicht gestattet, soweit nicht ausdrücklich zugestanden. Alle Rechte vorbehalten.