

# VERTIV™ BBE PRO SERIES

URB Broadband Edge Enclosures



## KEY FEATURES

- Universal Rear-mounting Bracket (URB) accommodates most optical terminal blocks.
- Ample space provided for fiber bend radius.
- "Stake-less" self-supporting base eliminates the need for supplemental mounting stakes.
- Split/Rehab base allows for easier placement over existing cable or pedestal expansion.
- Lift-off dome for 360° access permits complete access to all wirework and equipment.
- Seamless integral flood dome protects wirework from flood submersion; no joint worries.
- Single point self-locking cover provides secure pedestal locking, and eased craft access.
- Short self-supporting split base with or without snap-on mounting stake.

## Description

The Vertiv™ BBE PRO Series of non-metallic pedestals from Vertiv incorporates strength, rigidity and security all in a high performance thermo-plastic material designed to Telcordia GR-13 CORE specifications. A Universal Rear Bracket (URB) is mounted to the back of the pedestal, providing access to fiber drops and allowing for generous fiber bend radii, routing and future application growth.

The craft-friendly design provides optimal working space for optical terminal block attachment and conduit placement. Installation is simplified through the split/rehab base design and self-latching dome. To accommodate varying soil conditions, supplemental mounting stakes are available if additional stability is required.

## Application

Vertiv BBE PRO Series pedestals are ideal for applications where non-metallic construction, flood protection, or 360° access is desired. These pedestals are designed for optical terminal blocks in buried distribution FTTH applications.



*8-in. Fiber Pedestal*


*Shown with Self-Supporting Base  
and Universal Rear Bracket*

*(fiber terminal block not included)*

### Dimensions

PED	A	A	B*	C	D	E
	Short Self Supporting Base	Snap on Stake or Integral Spade				
Pro6	45- in.	65- in.	35- in.	30- in.	9- in.	6.5- in.
Pro8	45- in.	65- in.	35- in.	30- in.	10.5- in.	8- in.
Pro10	45- in.	65- in.	35- in.	30- in.	12- in.	10.8- in.
Pro 12	45- in.	60- in.	35- in.	30- in.	14.5- in.	11.5- in.

\*Height of enclosure above ground.

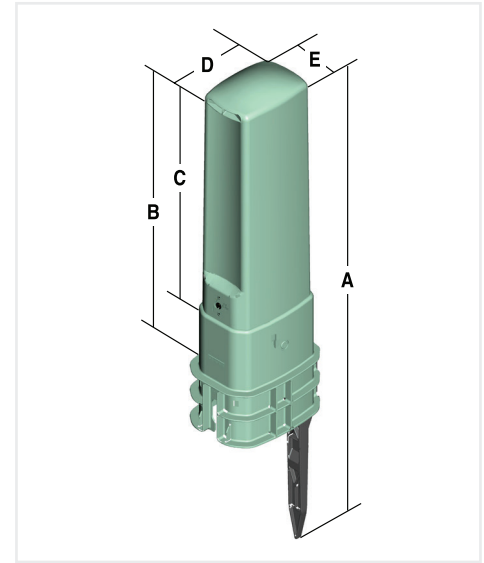

Short Self-Supporting Base  
Shown with Snap-On Stake

### Ordering Information

VERTIV CATALOG NO.	VERTIV PART NO.	DESCRIPTION
PRO6FINGURB	F1007872	6" split base pedestal with snap-on mounting stake and URB
PRO6FSNGURB	F1007873	6" split base pedestal with URB
PRO8FINGURB	F1006245	8" split base pedestal with snap-on mounting stake and URB
PRO8FSNGURB	F1006243	8" split base pedestal with URB
PRO10FINGURB	F1006246	10" split base pedestal with snap-on mounting stake and URB
PRO10FSNGURB	F1006244	10" split base pedestal with URB
PRO12FINGURB	F1006857	12" split base pedestal with integral spade and URB
PRO12FSNGURB	F1006856	12" split base pedestal with URB

### Accessories

VERTIV CATALOG NO.	VERTIV PART NO.	DESCRIPTION
URBKIT	F1006936	URB upgrade kit for Vertiv BBE PRO Series pedestals
MS1332	F602132	32 -in. mounting stake for pedestal, 10 each
MS1342	F604080	42-in. mounting stake for pedestal, 10 each
PROSPADE	F1008603	Non-metallic snap-on stake (PRO6, PRO8 and PRO10 only), 10 each

VertivCo.com | Vertiv Headquarters, 1050 Dearborn Drive, Columbus, OH, 43085, USA

© 2018 Vertiv Co. All rights reserved. Vertiv and the Vertiv logo are trademarks or registered trademarks of Vertiv Co. All other names and logos referred to are trade names, trademarks or registered trademarks of their respective owners. While every precaution has been taken to ensure accuracy and completeness herein, Vertiv Co. assumes no responsibility, and disclaims all liability, for damages resulting from use of this information or for any errors or omissions. Specifications are subject to change without notice.