

# VERTIV™ BBE BD SERIES

NSFBD Fiber Distribution Kit



## KEY FEATURES

- Two-sided, closed architecture design.
- Conveniently stores fiber slack and spliced drops in separate compartments.
- Holds up to 5 splice trays per side.
- Accommodates 15 feet of slack cable (144-fiber loose tube).
- Central Strength Member (CSM) clamps provide strain relief for fiber cable.
- Includes a radius limiting spool to protect fiber from bending damage.
- Easily installs within any UPCBD4 or UPCBD5 pedestal.

This closed architecture kit instantly converts any standard UPCBD4/5 pedestal into a fiber distribution pedestal.

## Description

The Vertiv™ BBE BD Series Fiber Distribution Kit easily mounts inside any standard UPCBD4 or UPCBD5 pedestal, converting it into a fiber distribution pedestal. The two-sided closed architecture configuration provides optimum environmental protection for fiber equipment against debris, insect and rodents. In addition, there is ample space for fiber slack storage and spliced drops in the two enclosed compartments.

Knockouts on the rear of the UPCBD pedestal are used to mount the kit. This minimizes the need to stock multiple pedestals, since the same pedestal style can be used for fiber or copper applications.

## Application

Designed for use in most FTTH applications, the Vertiv BBE BD Series Fiber Distribution Kit converts any standard UPCBD pedestal into a closed architecture, environmentally protected fiber distribution pedestal.




*Kit Shown Installed with Cover On  
(UPCBD4 pedestal sold separately)*




*Feeder and Drop Sides Shown  
Installed with Cover Off  
(UPCBD5 pedestal sold separately)*

## Diagrams

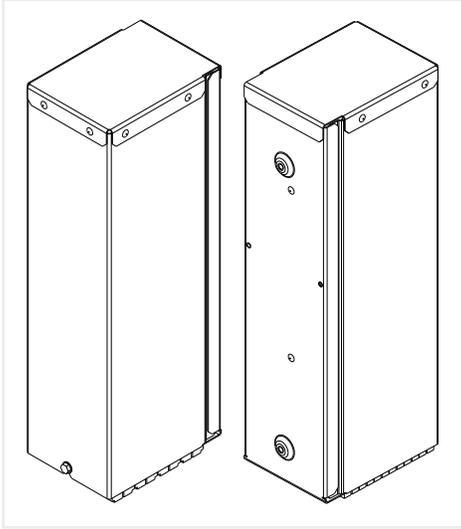

Exterior Front and Back of Closure  
(Isometric View)

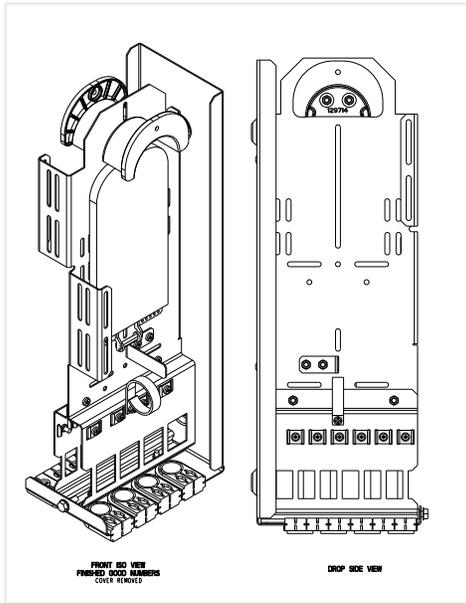

Interior Feeder Side (Isometric View)  
and Drop Side (Straight On View)

## Technical Specifications

CLOSURE	
Dimensions	21" x 7.5" x 5.6" (H x W x D)
Weight	15 lbs.
CABLE PORTS	
Feeder Side	(4) ports up to 0.90" OD cable
Drop Side	(6) dual ports up to 0.56" OD cable
STORAGE	
Splice Trays	Holds (5) splice trays up to 5" wide and 10.5" tall, per side (maximum stack height of 2.5 inches)
Fiber Slack	15.5 feet of 144-fiber loose tube

## Ordering Information

CATALOG NUMBER	PART NUMBER	DESCRIPTION
NSFBDCSCX	F1010627	Fiber distribution kit without splice tray
NSFBDCSC1	F1010628	Fiber distribution kit with (1) splice tray
UPCBD Pedestals		
UPCBD4	F604880	8-inch gray-green metal pedestal
UPCBD5	F604900	10-inch gray-green metal pedestal
Accessories		
NSST2448E	F1010586	Fiber splice tray; 24 single fusion or 4 mass fusion
MS1332	F602132	32-inch metal mounting stake
MS1342	F604080	42-inch metal mounting stake