

Table of Contents

Table of Contents ..... 2

Decals ..... 3

Locking Devices..... 3

UPCBD Series Pedestal Mounting Plates ..... 4

TV Series Pedestal Mounting Bracket ..... 5

Ground Bracket Kits ..... 6

Grounding/Bonding Straps..... 7

Grounding/Bonding Lugs ..... 7

Grommets..... 8

Miscellaneous ..... 8

Pad-Mounting Brackets..... 9

Pole Mounting Brackets ..... 9

MS Single-Mount Stakes..... 10

Mounting Posts ..... 11

Cable Guards..... 12


Spray Paint..... 13

## DECALS

### Ordering Information & Dimensions

Catalog Number	Part Number	Description	Height	Width
UP35MY	F600080	Caution buried cable decal, Independent, black on yellow, RUS accepted (10 pk)	6"	3"

**Note:** Our adhesive backed pressure sensitive decals are made of vinyl or Mylar with silk-screened print used for identifying equipment closures.

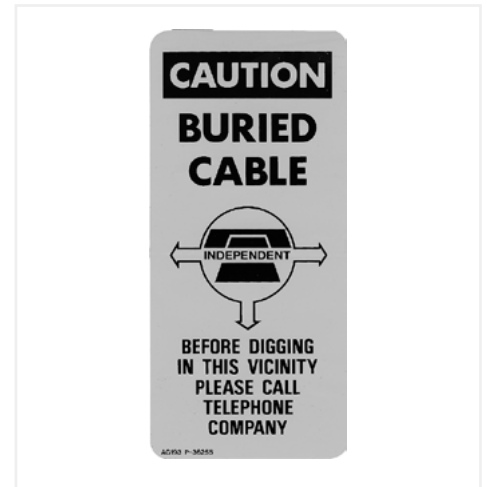

UP35MY

## LOCKING DEVICES

### Ordering Information

Catalog Number	Part Number	Description	Usage
TF75	F600490	1/4-20 x 51/64 with cupped washer around hex head, mounting bracket and key sold separately	Most telephone pedestals
TVHASP	F605887	TVHASP replacement hasp (10/pkg)	TV40, TV60LP, TV80, TV710, and TV104
38	F003205	216-Type "can wrench", hex key. Color may vary.	Finger-type wrench has hex end for 3/8" and 7/16" deep sockets. Ends for use on pedestals, cabinets and cross-connects.
P29732	F529732	T-handle tamper-proof wrench, 5/16 hex-wrench with 15 diameter bolts in recess both ends, 1 per package	Red handle wrench used on tamper-proof cross-connect cabinets, MESA®, and CATV enclosures



TF75  
1/4-20 CUP SEMS Bolt



38  
Can Wrench



TVHASP  
Replacement Hasp



P29732  
T-Handle Tamper-Proof Wrench

## UPCBD SERIES PEDESTAL MOUNTING PLATES

### Ordering Information

Catalog Number	Part Number	Description	Usage
BDURBKIT	F1011120	Accessory mounting bracket kit for optical or copper terminal blocks	UPCBD3, 4 and 5 closures
SB234	F604110	Stand-off bracket for terminal blocks and load-coil mounting Term Blocks, 281, 283, 381, 383, 145 and RPT A-Line Series	UPCBD2, UPCBD3, and UPCBD4 series closures, RUS accepted
SL1200	F602420	Splice support bars, 1 pkg, 1 lb.	UPC1200 and UPCBD7 series closures


\* Above plates used for mounting BT25 or RLS25 blocks (three per plate), load coils, and repeaters. The HIACT100 has two plates per kit, and the HIACT300 has three plates per kit.



*BDURBKIT*



*SB234  
Stand-Off Bracket*

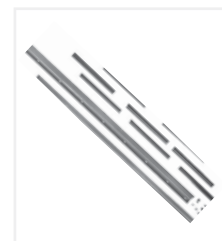

*SL1200  
Splice Support Bars*

# TV SERIES PEDESTAL MOUNTING BRACKETS

## Ordering Information


Catalog Number	Part Number	Description	Usage
OS	F606793	Off-set equipment mounting bracket with hardware, 1 per package	TV40, TV60, TV80, TV104, and TV106
AS	F603230	Equipment mounting bracket with hardware, 1 per package	TV80, TV104, and TV106
SM	F603240	Painted cross-slot mounting plate with hardware, 14-3/4" high x 5" wide, 1 per package	TV80, TV104, and TV106
LM	F603220	Large painted cross-slot mounting plate with hardware, 1 per package	TV106




OS  
Mounting Bracket



AS  
Mounting Bracket

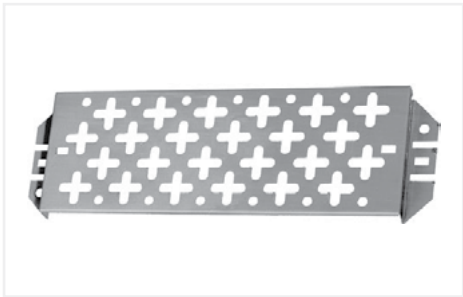

SM  
Mounting Plate

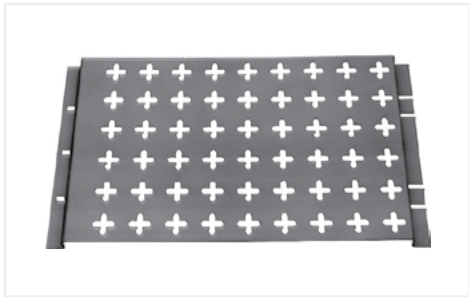


LM  
Mounting Plate


## GROUND BRACKET KITS



GBRBD2  
Ground Bracket Kit

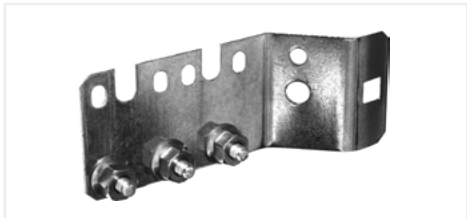

GBRREA  
Ground Bracket Kit

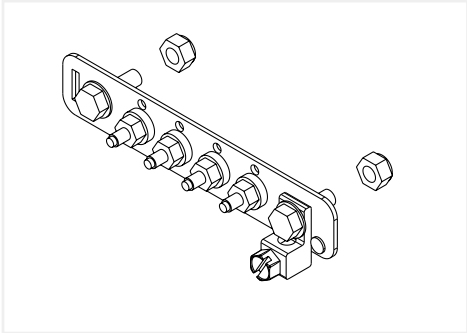

PROGENGNDKIT  
4-Position Ground Bar Kit



GBREXT  
Stud-Mount Extension Bracket



GRDEXTKIT  
Channel-Mount Extension Bracket

## Ordering Information

Catalog Number	Part Number	Description	Usage
GBRBD2	F605113	Ground bracket kit	UPCBD2
GBRREA*	F605112	Ground bracket kit	UPCBD3, 4, and 5 closures, RUS accepted
PROGENGNDKIT	F1007704	4-position ground bar kit	ProFORM™ pedestals
GBREXT	F605114	Stud-mount extension bracket. Install below isolation bracket.	All pedestal closures that use standard shield isolation brackets except for UPCBD2
GRDEXTKIT	F605115	Channel-mount extension bracket. Install above insolation bracket.	All pedestal closures that use standard shield isolation brackets except for UPCBD2

\* Replaces GBRUPCBD. Install with existing mounting hardware. Additional mounting hardware, Catalog Number P39869, may be ordered separately.

\*\* P36790 bracket is used for field rehab when changing from existing series bonding/grounding to shield isolation style.

## GROUNDING/BONDING STRAPS



P41545  
Tin Plated Bond Braid Strap



P51865  
Copper Ground Wire Strap

### Ordering Information

Catalog Number	Part Number	Description	Usage
P41545	F541545	6 AWG tin plated bond braid, round, flexible, 20" long with .205 diameter mounting holes for #10 screws	All closures
P51865	F551865	Solid 6 AWG copper ground wire, 20" long with .203 diameter mounting holes for #10 screws, 20 per package	All closures

## GROUNDING/BONDING LUGS



ALP387  
Bonding/Grounding  
Connector



UP5006  
Fargo Ground  
Connector



TVSTDGLK  
Ground Lug Kit



P43197  
Bonding Clamp

### Ordering Information

Catalog Number	Part Number	Description	Usage
ALP387*	F605130	Bronze, electro-tin plate, hex-head bonding/grounding connector	All closures and UPCBD series closures for RUS, UL 486A, and UL 467
UP5006**	F600021	Fargo ground connector	All closures
TVSTDGLK	F605884	Ground lug kit for classic style pedestals, 1 per package	TV40, TV60LP, TV80, TV104, TV106, and TV710
P43197***	F543197	"C" Service (drop) wire cable shield bonding clamp	All closures, 50 per package

\* Above lugs for use in system grounding using 6AWG solid ground wire.

\*\* Above lug for use with shielded service wire.

\*\*\* For use on shielded or unshielded service wire.

## GROMMETS



SWG & SWGB  
Rubber Service Wire Grommet

### Ordering Information

Catalog Number	Part Number	Description	Usage
SWG*	F600270	Green 3/4" rubber service wire grommet, 50 per pkg, 1 lb.	All closures
SWGB*	F600269	Black 3/4" rubber service wire grommet, 50 per pkg, 1 lb.	All closures

\* Temporary service-wire grommet.

## MISCELLANEOUS



P20229X  
Wire Grooming Clip

### Ordering Information

Catalog Number	Part Number	Description	Usage
P20229X	F600271	3/4" wire grooming clip for .250 square hole	Mounting plates in many pedestals, WP, RNV, OBT, MC10, BET, BEF, LC cross-connect, ONUs and R366 & 2391 protected connectors and blocks

\* For use when stake mounting knockout has been removed and not used.



## PAD-MOUNTING BRACKETS



*PADMT200300  
Pad-Mounting Bracket Kit*

### Ordering Information

Catalog Number	Part Number	Description	Usage
PADMT200300	F605650	Pad-mounting bracket kit for surface mounting on top of pad	UPCBDS200, UPCBDS300, UPCBD7, UPC1200 series, TV2400, TV2500, OPFOTV7, OPFOTV8, ECQF/ERLS series closures, RUS accepted


## POLE MOUNTING BRACKETS



*PKGPM  
Mounting Hardware*

### Ordering Information

Catalog Number	Part Number	Description
PKGPM	F602780	Metal pole-mounting hardware for all closures, RUS accepted
PROPOLEMTG	F1007865	Metal pole-mounting bracket for ProForm pedestals

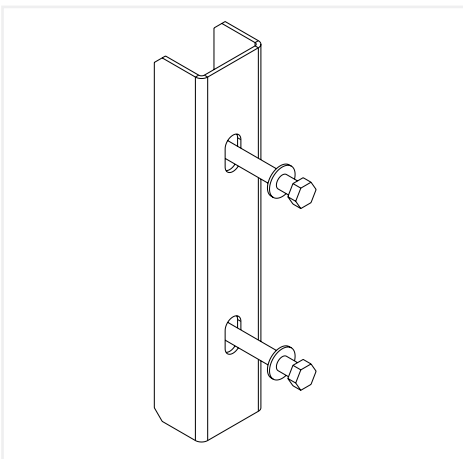

*PROPOLEMTG  
Pole-Mounting Bracket*

MS SINGLE-MOUNT STAKES



MS13 Series  
Single-Mount Stake

Ordering Information

Catalog Number	Part Number	Description	Usage
Single Mount Stakes			
MS1324	F603272	24" stake with hardware, green	Pedestals and closures
MS1332	F602132	32" stake with hardware, green	Pedestals
MS1342	F604080	42" stake with hardware, green	Pedestals and closures, RUS accepted
Stake Mounting Equipment and Hardware			
UPCBDHDW	F601410	Standard stake mounting hardware	MS1324, MS1332, MS1342, MS1354 stakes, RUS accepted



UPCBDHDW  
Standard Stake Mounting Hardware

## MOUNTING POSTS

### Description

The mobile home post (MHP) is a heavy-gauge three position U-shaped channel post on which a 3.5 x 20.0-inch adjustable multi-position mounting plate is attached. The mounting plate provides universal mounting slots that will accept a variety of Network Interface Devices and station protectors. The elongated oval service wire holes help eliminate any sharp bending of service wires as they exit from behind the mounting plate to the protector unit. The slots provided in the channel posts are used for cable ties to help secure service wires inside the U-shaped channel.

The PMP posts are designed for mounting one or two-pair station protection. The posts are manufactured of heavy gauge mill-galvanized steel, treated with a unique gray-green finishing process for longer life.

### Application

The MHP is designed for mounting one or more Network Interface Device or station protector in mobile home parks or anywhere a mobile home trailer is used and buried service wires are used to provide telephone or CATV service. This design replaces our two current mounting posts.

### Ordering Information

Catalog Number	Part Number	Description
MHP	F602202	Multi-position mobile home post, adjustable to 36.5", 42.5" and 48.5"
MHP36	F602190	36" fixed position mobile home post
MHP48	F602200	48" fixed position mobile home post
PMP38	F604370	Protector mounting post, 38", 3" x 5-1/2" mounting plate
PMP50	F604380	Protector mounting post, 50", 3" x 5-1/2" mounting plate

**Note:** MHP will mount one and two pair station protectors and the following network interface devices (NIDs): Keptel Series SNI 1100/1200, 2100/2200, 4300, 4600, 4600xl - Seicor Series SNI CAC900, 7600, 9600, MLP600, NI2006, ONI200 - Joslyn Series 7005, 7032, 7090 - TII Series 3610H, 3710H



MHP  
Mobile Home Post



PMP  
Protector Mounting Post

CABLE GUARDS

Key Features

- Flanged edges do not require additional brackets for installation for greater ease of use and installation.
- Available in convenient sizes for application flexibility and ease of installation.
- Direct mounting for extended protection.
- Made of heavy gauge steel for durability and low maintenance costs.
- Provided with our proprietary gray-green paint for longer life.



UP3758G  
Steel U-Guard


Description

U-Guards are strapless flanged u-shaped cable guards, manufactured of heavy gauge steel, with a gray-green finish and .312 x .438 slotted mounting holes. Sold in packages of 50.

Application

U-Guards protect cable mounted along a wall or pole and splice points.

Diagram

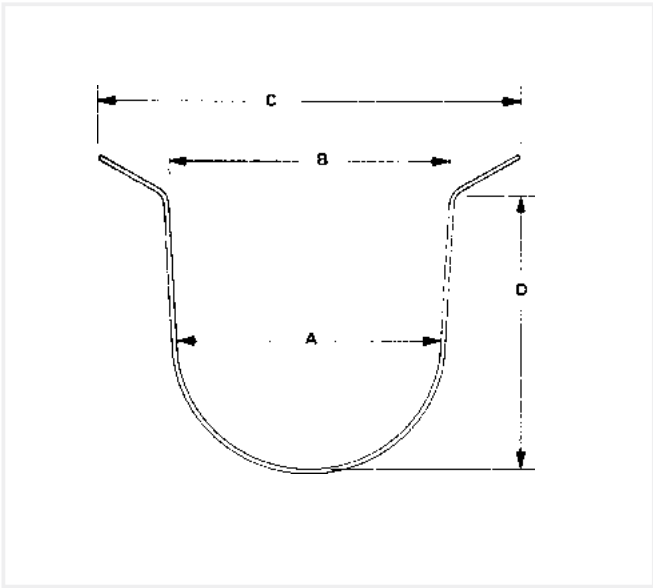

Metal U-Guard

Ordering Information

Catalog Number	Part Number	Description
Steel U-Guards		
UP758G	F601550	3/4" ID x 8', green finish
UP1258G	F601570	1-1/4" ID x 8', green finish
UP2258G	F601590	2-1/4" ID x 8', green finish
UP3258G	F601610	3-1/4" ID x 8', green finish
UP3758G	F601630	3-3/4" ID x 8', green finish

SPRAY PAINT



TU20  
Spray Paint

Ordering Information

Catalog Number	Part Number	Description	Usage
TU17*	F600540	Gray-green spray paint	All closures
TU20*	F600571	Beige spray paint	All closures
TU27*	F600556	Off-white glossy spray paint	All closures
P90370	F590370	Small bottle, off-white touch-up paint with brush	All off-white closures (can ship air)

\* Cannot ship via air.

