

NETSPAN™ PROFORM MI SERIES

Broadband Edge Enclosures



KEY FEATURES

- Metal fiber mounting plate accommodates slack storage on one side and splicing on the other.
- Radius limiting spools improve fiber management and reduce chance of signal loss.
- Accommodates up to 12 feet of 144 loose tube fiber and up to 6 splice trays (12" H x 4.5" W).
- Lift-off dome for 360° access permits complete access to all wirework and equipment.
- Seamless integral flood dome protects wirework from flood submersion; no joint worries.
- Single point self-locking cover provides secure pedestal locking, and eased craft access.
- Short self-supporting split base with or without snap-on mounting stake.
- Meets or exceeds RUS requirements

The NetSpan™ ProForm MI Series is designed for high speed buried distribution applications at the network edge.


Description

The NetSpan ProFORM FTTP MI Series of non-metallic pedestals incorporates strength, rigidity and security all in a high performance thermo-plastic material designed to Telcordia GR-13 CORE specifications.

The MI Series of FTTP pedestals provides fiber distribution on a center mounted metal insert. The craft-friendly design of the ProFORM pedestal ensures ample working space for fiber management and conduit placement, and the fiber distribution mounting plate is designed for slack storage, splicing and drops. Installation is simplified through the split/rehab base design and self-latching dome, and to accommodate varying soil conditions, supplemental mounting stakes are available if additional stability is required.

Application

The NetSpan ProFORM FTTP MI Series is ideal for applications where non-metallic construction, flood protection, or 360° access is desired. These pedestals are designed for slack storage, fiber splicing and drops in buried distribution FTTH applications.

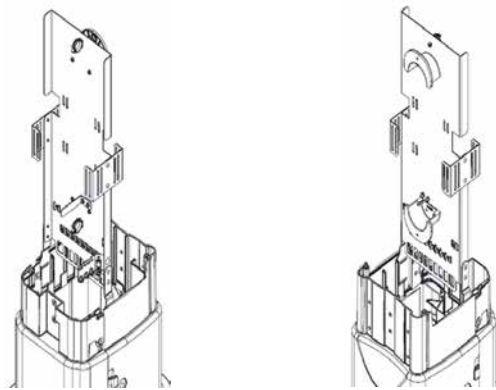

Front

Rear

10-in. Fiber Pedestal

Front & Back Views with Self-Supporting Base and Metal Insert
(fiber cable & splice trays not included)

Dimensions

PEDESTAL	A	A	B*	C	D	E
	Short Self-Supporting Base	Snap-On Stake or Integral Spade				
Pro8	45-in.	65-in.	35-in.	30-in.	10.5-in.	8-in.
Pro10	45-in.	65-in.	35-in.	30-in.	12-in.	10.8-in.

* Height of enclosure above ground.

Ordering Information

CATALOG NUMBER	PART NUMBER	DESCRIPTION
PRO8FING	F1007237	8" split base pedestal with snap-on mounting stake and fiber mounting plate
PRO8FSNG	F1007238	8" split base pedestal with fiber mounting plate
PRO10FING	F1007239	10" split base pedestal with snap-on mounting stake and fiber mounting plate
PRO10FSNG	F1007240	10" split base pedestal with fiber mounting plate
Accessories		
PRO8FMPLT	F1007331	Fiber mounting plate for 8" ProFORM® pedestals
PRO10FMPLT	F1007168	Fiber mounting plate for 10" ProFORM pedestals
NSST2448E	F1010586	Universal splice tray, 24 single fusion or 4 mass fusion (48 fibers) (for PRO8 and PRO10), 10 each
MS1332	F602132	32-inch mounting stake for pedestal, 10 each
MS1342	F604080	42-inch mounting stake for pedestal, 10 each
PROSPADE	F1008603	Non-metallic snap-on stake (PRO6, PRO8 and PRO10 only), 10 each

Diagrams



Short Self-Supporting Base Shown with Snap-On Stake



Universal Splice Tray