

Vertiv™ Knürr® System Accessories

Features

BLANKING PANELS

- Design identical to racks
- Tool-less, threaded version available.
- Varying sizes for quick mounting and efficient cooling.

CHASSIS RAILS

- Various designs catering to different requirements.
- Height positioning for different corpus heights of the subracks possible (not defined according to 19" standard).

DRAWERS AND SHELVES

- Various designs catering to different loads.
- Shelves with tool-less mounting available.

Mechanical accessories are fundamental to effective and economical use of server- and network racks.

Blanking panels are an essential feature in operating an energy-efficient data center, as they ensure that cold and warm air in the rack are separated.

When there are no mounting adapters for IT components, chassis rails are required.

Drawers are used to store manuals, spare parts and tools needed on site.





MEC20179

QuickFix 19" blanking panel Tool-less assembly

- For covering free 19" spaces (cold-hot separation).
- Quick and easy tool-less assembly (one click) and disassembly (quarter turn).
- Suitable for 9.5 x 9.5 square holes.

Material

- Sheet steel, 10 mm.

Finish

- Final digit of order number .1: powder-coated texture, RAL 7035, light-grey.
- Final digit of order number .8: powder-coated texture, RAL 7021 dark-grey.

Scope of delivery

- X (see Order Number for quantity) QuickFix 19" blanking panel.
- Mounting kit.

How supplied

- In sets (see Order Number for quantity); fixing clips pre-assembled.



MEC20180



MEC20178

W	H	U	Order No.	UP
482.6	43.6	1	01.103.301.X	6 units
482.6	88.1	2	01.103.302.X	3 units
482.6	132.5	3	01.103.303.X	2 units
482.6	265.9	6	01.103.306.X	1 unit
482.6	399.2	9	01.103.309.X	2 units
482.6	932.6	21	01.103.321.X	1 unit



MEC20181

19" QuickFix blanking panel, tool-less assembly

- For orderly cable management inside the rack.
- Quick and easy tool-less assembly (one click) and disassembly (quarter turn).
- Suitable for 9.5 x 9.5 square holes.

Material

- Sheet steel, 10 mm.

Finish

- Final digit of order number .1: powder-coated texture, RAL 7035, light-grey.
- Final digit of order number .8: powder-coated texture, RAL 7021 dark-grey.

Scope of delivery

- 6 x QuickFix 19" blanking panel cable ports.
- 1 x Mounting kit.

How supplied

- In sets (clips pre-assembled).




MEC20178



MEC20229

W	H	U	Order No.	UP
482.6	43.6	1	01.103.331.X	6 units

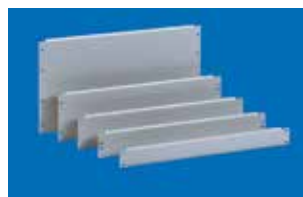

CUD00005

19" blanking plate Screw-on

- For covering free 19" spaces (cold-hot separation).

Material

- Sheet steel, 10 mm.

Finish

- Final digit of order number .1: powder-coated texture, RAL 7035, light-grey.
- Final digit of order number .8: powder-coated texture, RAL 7021 dark-grey.

Scope of delivery

- X (see Order Number for quantity) QuickFix 19" blanking panel.

How supplied

- In sets (see ON for quantity).

Note

- Please also order front panel mounting material.



CUD00004

W	H	U	Order No.	UP
482.6	43.6	1	01.103.201.X	6 units
482.6	88.1	2	01.103.202.1	3 units
482.6	88.1	2	01.103.202.X	3 units
482.6	132.5	3	01.103.203.X	2 units
482.6	265.9	6	01.103.206.X	1 unit
482.6	399.2	9	01.103.209.X	2 units



LUF88006

19" vented front cover plate

- Provides additional ventilation for 19" racks and 19" plinths compliant with IEC 297.

Material / Color

- Final digit of order number .1: ABS (UL 94 V0), light-grey RAL 7035.
- Final digit of order number .9: ABS (UL 94 V0), black RAL 9011.

Scope of delivery

 
- 1 x vented front cover plate.
- 2 x connectors.

How supplied

- In sets.

Note

- Please also order the appropriate mounting kit for the front plates.




LUF00093


W	H	U	Order No.	UP
483	43.6	1	02.008.111.1	1 unit
483	43.6	1	02.008.111.9	1 unit

= assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.

Dimensions in mm:				Conversion:
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch
H = Height	d = Insertion depth	(1U = 44.45 mm)		1 kg = 2.2046 pounds
D = Depth	L = Length	UP = Packaging unit		

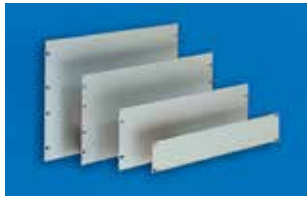

FRO00005

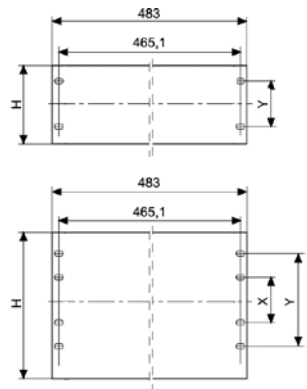

MEC20109

19" front plate Aluminum 3 mm

- **Material / Finish**
 - Final digit of order number .0: AlMg3 - F23 polished with lamination sheet.
 - Final digit of order number .1: AlMg3 - F23, powder-coated, RAL 7035, light-grey.
 - Final digit of order number .6: AlMg3 - F23 EB (anodize-enabled), anodized E6/EV1.
 - Final digit of order number .8: AlMg3 - F23, powder-coated, RAL 7021, dark-grey.

- **Scope of delivery**
 - 1 x 19" front plate.

- **How supplied**
 - Single items.

- **Note**
 - Please also order the appropriate mounting kit for the front plates.

H	X	Y	U	Model	Order No.	UP
436		31.7	1	Polished	02.008.021.0	1 unit
436		31.7	1	Powder-coated, RAL 7035	02.008.021.1	1 unit
881		76.2	2	Powder-coated, RAL 7035	02.008.022.1	1 unit
132.5		57.1	3	Powder-coated, RAL 7035	02.008.023.1	1 unit
1770		101.6	4	Powder-coated, RAL 7035	02.008.024.1	1 unit
265.9	76.2	190.4	6	Powder-coated, RAL 7035	02.008.026.1	1 unit
436		31.7	1	Powder-coated, RAL 7021	02.008.021.8	1 unit
436		31.7	1	Anodized	02.008.071.6	1 unit
881		76.2	2	Anodized	02.008.072.6	1 unit
132.5		57.1	3	Anodized	02.008.073.6	1 unit
1770		101.6	4	Anodized	02.008.074.6	1 unit
265.9	76.2	190.4	6	Anodized	02.008.076.6	1 unit



MEC20144



MEC20149

Cover-plate filter for 19" vented front cover plate

- Used with 19" vented front cover plate.

- **Material / Color**
 - Non-woven and screen cloth.

- **Scope of delivery**
 - 1 x cover-plate filter.
 - 1 x Mounting kit.


- **How supplied**
 - In sets.

- **Note**
 - Appropriate for 02.008.111.X

U	Order No.	UP
1	02.008.131.9	1 unit



LUF00217

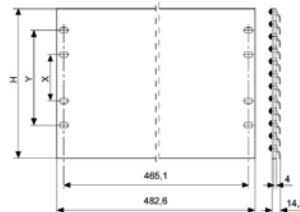

MEC20110

19" ventilation front panel

- Provides additional ventilation for 19" racks and 19" plinths compliant with IEC 297.

- **Material**
 - Aluminum.

- **Finish**
 - Final digit of order number .1: powder-coated, RAL 7035 light-grey.
 - Final digit of order number .6: colorless anodized E6 / EV 1.

- **Scope of delivery**
 - 1 x ventilation front plate.

- **How supplied**
 - Single items.

- **Note**
 - Please also order the appropriate mounting kit for the front plates.

H	Y	U	Model	Order No.	UP
436	31.7	1	Powder-coated, RAL 7035	02.008.101.1	1 unit
436	31.7	1	Anodized	02.008.101.6	1 unit
132.5	57.1	3	Powder-coated, RAL 7035	02.008.103.1	1 unit
132.5	57.1	3	Anodized	02.008.103.6	1 unit



FRO00007

19" front plate hinged

- With 19" adapter and hinge.


- **Material**
 - Aluminum, 3 mm.

- **Finish**
 - Anodized.

- **Scope of delivery**
 - 1 x front plate, hinged.
 - 1 x 19" adapter.
 - 1 x hinge.

- **How supplied**
 - In sets.

- **Note**
 - Please also order the appropriate mounting kit for the front plates.

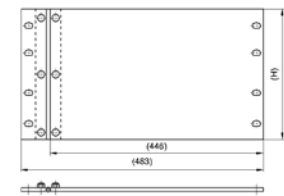

FRO00006

U	Model	Order No.	UP
3	Anodized	01.110.780.6	1 unit
6	Anodized	01.110.781.6	1 unit



MEC20162

Chassis runner

Can be hooked on and screwed on

- For installation in 19" rack and 19" enclosure.
- Can be hooked on for quick and easy mounting.
- Can also be attached with screws to accommodate heavier loads.
- Can be screwed from inside (used in rack suites).
- Adjustable height to suit various main-section heights.

Material / Finish

- Sheet steel, 2.0 mm.
- Zinc-passivated, blue chrome-plated.

Load rating

- 1000 N max. with even load distribution.

Scope of delivery

- 2 x chassis runners.
- 1 x Mounting kit.

How supplied

- In pairs.

Note

When selecting the chassis runner, please take into account the depth "d" of the rack or enclosure. Four 19" extrusions are required for mounting.

- Mounting adapter for 19" server extrusions 01.147.640.9 1 Set.
- Mounting adapter for Smaract 19" server extrusions 01.127.119.9 1 Set.



MEC20167



MEC20167

D _{Rack}	d	L	For rack type	Order No.	UP
600	365	336	MIR2 / DCM / Smaract	01.103.051.0	1 pair P
600	440	411	MIR2 / DCM / Smaract	01.103.052.0	1 pair
800	565	536	MIR2 / DCM / Smaract	01.103.053.0	1 pair P
800	640	611	MIR2 / DCM / Smaract	01.103.054.0	1 pair
900	665	636	MIR2 / DCM / Smaract	01.103.055.0	1 pair
from 900	740	711	MIR2 / DCM / Smaract / CoolTherm	01.103.056.0	1 pair P



MEC20189

Aluminum chasis runner

- Can be screwed on.
- For installation in 19" rack and 19" enclosure.
- Can be screwed from inside (used in rack suites).
- Height can be adjusted to suit various main-section heights.

Material / Finish

- Extruded aluminum, polished.

Load rating

- 700 N max. with even load distribution.

Scope of delivery

- 2 x chassis runners.
- 1 x Mounting kit.

How supplied

- In pairs.

Note

When selecting the chassis runner, please take into account the depth "d" of the rack or enclosure. Four 19" extrusions are required for mounting.

- Mounting adapter for 19" server extrusions 01.147.640.9 1 Set.
- Mounting adapter for Smaract 19" server extrusions 01.127.119.9 1 Set.

D _{Rack}	d	L	For rack type	Order No.	UP
600	365	336	MIR2 / DCM / Smaract	01.103.101.0	1 pair P
600	440	411	MIR2 / DCM / Smaract	01.103.102.0	1 pair
800	565	536	MIR2 / DCM / Smaract	01.103.103.0	1 pair P
800	640	611	MIR2 / DCM / Smaract	01.103.104.0	1 pair P
800	665	636	MIR2 / DCM / Smaract	01.103.105.0	1 pair
from 900	740	711	MIR2 / DCM / Smaract / CoolTherm	01.103.106.0	1 pair P
500	285	254	ConAct	01.103.111.0	1 pair
600	385	354	ConAct	01.103.112.0	1 pair
600	435	403	DoubleProRack with door	01.103.118.0	1 pair
800	635	603	DoubleProRack with door	01.103.119.0	1 pair
500	460	428	DoubleProRack, no door	01.103.122.0	1 pair
600	560	528	DoubleProRack, no door	01.103.123.0	1 pair
700	660	628	DoubleProRack, no door	01.103.124.0	1 pair
800	760	728	DoubleProRack, no door	01.103.125.0	1 pair

P = assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.

Dimensions in mm:				Conversion:
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds
D = Depth	L = Length	UP = Packaging unit		



MEC20163

Chassis runner, adjustable depth

- For installation in 19" rack and 19" enclosure.
- Adjustable depth.
- Can be screwed from inside (used in rack suites).
- Height can be adjusted to suit various main-section heights.

Material / Finish

- Sheet steel, 1.25 mm.
- Zinc-passivated, blue chrome-plated.

Load rating

- 200 N max. with even load distribution.

Scope of delivery

- 2 x basic rails.
- 2 x extension rails.
- 1 x Mounting kit.

How supplied

- In pairs.

Note

- When selecting the chassis runner, please take into account the depth "d" of the rack or enclosure. Four 19" extrusions are required for mounting.
- Mounting adapter for 19" server extrusions 01.147.640.9 1 Set.
 - Mounting adapter for Smaract 19" server extrusions 01.127.119.9 1 Set.



MEC20166

D _{Rack}	d	For rack type	Order No.	UP	
600	355-570	MIR2 / DCM / Smaract	01.103.091.0	1 pair	P
800-1200	565-740	MIR2 / DCM / Smaract	01.103.092.0	1 pair	P
900-1200	740	CoolTherm	01.103.092.0	1 pair	P
600	385	ConAct	01.103.091.0	1 pair	
500-600	435-460	DoubleProRack	01.103.091.0	1 pair	
600-800	560-660	DoubleProRack	01.103.092.0	1 pair	P



MEC20270

19" shelf fixed

- Integrated mounting holes at front and rear for handle or cable cantilever.
- Perforated to optimize air supply.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.

Material / Finish

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Mounting rail, tableau: Sheet steel 1.0 mm, powder-coated texture

Color

- Final digit of order number .1: RAL 7035, light grey.
- Final digit of order number .8: RAL 7021 dark-grey.

Load rating


- 500 N static per item.

Scope of delivery

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Mounting rails.
- 1 Shelf board.
- 1 Extension board (from L = 600).
- Mounting kit.

How supplied

- In sets.

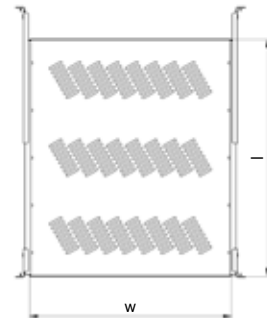


MEC20271

d _{insertion depth}	WxL	For rack type	Order No.	UP
365	426 x 300	MIR2 / DCM / Smaract	01.102.690.1.001	1 unit
440	426 x 300	MIR2 / DCM / Smaract	01.102.691.1.001	1 unit
565	426 x 500	MIR2 / DCM / Smaract	01.102.692.1.001	1 unit
565	426 x 500	MIR2 / DCM / Smaract	01.102.692.8.001	1 unit
640	426 x 600	MIR2 / DCM / Smaract	01.102.693.1.001	1 unit
640	426 x 600	MIR2 / DCM / Smaract	01.102.693.8.001	1 unit
740	426 x 600	MIR2 / DCM / Smaract	01.102.694.1.001	1 unit
740	426 x 600	MIR2 / DCM / Smaract	01.102.694.8.001	1 unit
435, 460	426 x 300	DoubleProRack	01.102.691.1.001	1 unit
560	426 x 500	DoubleProRack	01.102.692.1.001	1 unit
635, 660	426 x 600	DoubleProRack	01.102.693.1.001	1 unit
385	426 x 300	ConAct	01.102.690.1.001	1 unit

P = assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.

Dimensions in mm:				Conversion:
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds
D = Depth	L = Length	UP = Packaging unit		

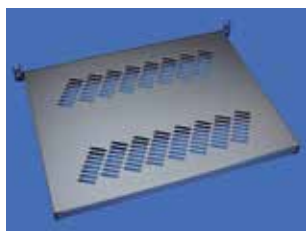

MEC20221

19" QuickFix shelf tool-less assembly

- Quick and easy tool-less mounting. Mounted on 19" cutouts.
- Quick and easy tool-less fitting (one click) and removal (quarter turn).
- Suitable for all racks and enclosures with 19" mounting hole extrusions (9.0 x 9.0 square holes).
- Adjustable depth to accommodate variable recess depths and special dimensions.
- Perforated to optimize air supply.

Material

- Sheet steel, 1.0 mm.

Finish

- Final digit of order number .1: powder-coated texture, RAL 7035, light-grey.
- Final digit of order number .8: powder-coated texture, RAL 7021 dark-grey.

Load rating

- 700 N static with even load distribution.

Scope of delivery

- 1 x 19" QuickFix shelf.
- 1 x Mounting kit.

How supplied

- In sets.

Note

- Cannot be used for 19" t-slot extrusions.
- Nothing may be attached on the first upper U otherwise the shelf can not be mounted in the 19" cutouts.

d _{insertion depth}	WxL	Order No.	UP
365-500	430 x 300	01.102.071.X	1 unit
565-740	430 x 500	01.102.072.1	1 unit
565-740	430 x 500	01.102.072.8	1 unit P



MEC20268

19" Shelf partial extension

- Integrated mounting holes at front and rear for handle or cable cantilever.
- Perforated to optimize air supply.
- Locks in extended position (friction lock).
- Quick separator for tool-less removal and decoupling of shelf board.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.

Material / Finish

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Tableau: Sheet steel 1.5 mm, powder-coated texture.

Color

- Final digit of order number .1: RAL 7035, light grey.
- Final digit of order number .8: RAL 7021 dark-grey.

Load rating


- 500 N static per item.

Scope of delivery

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Telescopic slides.
- 1 Shelf board.
- Mounting kit.

How supplied

- In sets.

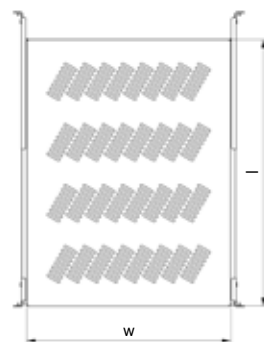

MEC20269

d _{insertion depth}	WxL	Order No.	UP
365-565	427 x 360	01.102.682.X.001	1 unit
565-750	427 x 560	01.102.683.X.001	1 unit

Dimensions in mm:				Conversion:	
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch	
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds	
D = Depth	L = Length	UP = Packaging unit			



MEC20266

19" Shelf full extension

- Integrated mounting holes at front and rear for handle or cable cantilever.
- Perforated to optimize air supply.
- Locks in extended position (friction lock).
- Quick separator for tool-less removal and decoupling of shelf board.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.

Material / Finish

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Tableau: Sheet steel 1.5 mm, powder-coated texture.

Color

- Final digit of order number .1: RAL 7035, light grey.
- Final digit of order number .8: RAL 7021 dark-grey.

Load rating


- 500 N static per item.

Scope of delivery

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Telescopic slides.
- 1 Shelf board.
- Mounting kit.


How supplied

- In sets.

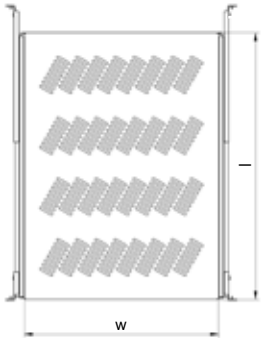

MEC20267

d _{insertion depth}	WxL	Order No.	UP
365-565	408 x 360	01.102.680.X.001	1 unit
565-750	408 x 560	01.102.681.X.001	1 unit

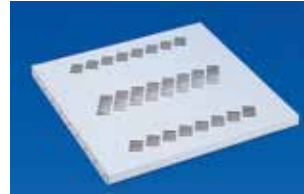

MEC00120

19" heavy-duty shelf fixed

- Perforated utility space.
- Installed as base plate for server or battery.

Material / Finish

- Sheet steel 1.5 mm, electroplated zinc, powder-coated texture.

Color

- Final digit of order number .1: RAL 7035, light grey.
- Final digit of order number .8: RAL 7021 dark-grey.

Load rating

- 1000 N static for CW installation.
- 1500 N static for 19" installation.

Scope of delivery


- 1 x shelf, fixed, threaded connection.
- 2 x mounting braces.
- 1 x Mounting kit.

How supplied

- In sets.

Note

- Please order requisite mounting adapter when used for Miracel 2/DCM 19" server extrusion.
 - Mounting adapter for 19" server extrusions 01.147.640.9 1 Set.
- Please order requisite mounting adapter when used for Smaract server extrusion.
 - Mounting adapter for 19" server extrusions 01.127.119.9 1 Set.

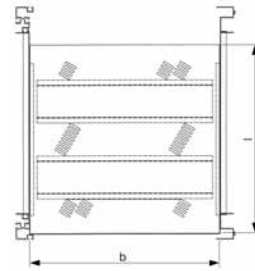

MEC20117

d _{insertion depth}	WxL	For rack type	Order No.	UP
565	467 x 460	MIR2 / DCM / Smaract	01.131.473.X	1 unit
640	467 x 460	MIR2 / DCM / Smaract	01.131.475.X	1 unit
665	467 x 460	MIR2 / DCM / Smaract	01.131.476.X	1 unit
740	467 x 560	MIR2 / DCM / Smaract	01.131.474.X	1 unit



MECxxxx

Cable cantilever

- For easy installation inside the rack/on the shelf; shelf or rack easily attached or decoupled with spring clip.
- Guarantees defined and kink-free cable routing.
- Minimum space requirement at the back of shelves 40 mm.

Material / Finish

- Sheet steel 1.5 mm, zinc passivated.

Scope of delivery

- 1 Cable cantilever.
- Mounting kit.

How supplied

- In sets.

Type	Order No.	UP
2-piece	01.102.728.0.001	1 unit

= assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.


Dimensions in mm:				Conversion:	
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch	
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds	
D = Depth	L = Length	UP = Packaging unit			



MEC20274

19" Heavy-duty shelf full extension

- Perforated to optimize air supply.
- Locks in retracted and fully extended position.
- Easy mounting with patented quick-mounting system.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.
- Installed as base plate for server or battery.

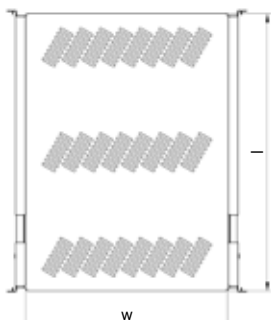

MEC20275

- **Material / Finish**
 - Mounting brackets: Sheet steel 2.0 mm, galvanized.
 - Tableau: Sheet steel 2.0 mm, powder-coated texture.
- **Color**
 - Final digit of order number .1: RAL 7035, light grey.
 - Final digit of order number .8: RAL 7021 dark-grey.
- **Load rating**
 - 1200 N static.
- **Scope of delivery**
 - 2 Mounting brackets front left / right.
 - 2 Mounting brackets rear left / right.
 - 2 Telescopic slides.
 - 1 Shelf board.
 - Mounting kit.
- **How supplied**
 - In sets.


d _{insertion depth}	WxL	For rack type	Order No.	UP
565-750	409 x 560	MIR2 / DCM / Smaract	01.102.711.X.001	1 unit



MEC20138

Handle

- Suitable for traditional and heavy-duty shelves.
- With M5 internal thread.
- **Material**
 - Die-cast aluminum consoles.
 - Extruded aluminum handles.
 - Cap made of ABS UL 94 HB.
- **Finish**
 - Handle, powder-coated, grey-blue, RAL 5008/ Cap, light-grey, RAL 7035.
- **Scope of delivery**
 - 2 x handles.

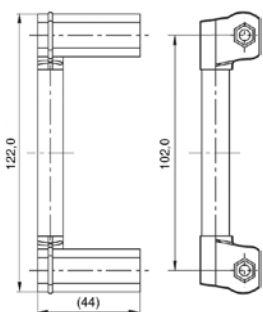

MEC20111


Order No.	UP
00.050.503.1	1 set



MEC20282

19" Shelf 2 U fixed

- For mounting in racks with fixed 19" installation at front.
- Quick and easy mounting on 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.
- Also for swing frame in the 19" rack and 19" enclosure.

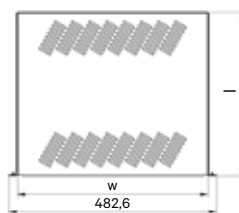

MEC20283

- **Material**
 - Sheet steel 1.5 mm, powder-coated texture.
- **Color**
 - Final digit of order number .1: RAL 7035 light-grey.
 - Final digit of order number .8: RAL 7021 dark-grey.
- **Load rating**
 - 200 N static.
- **Scope of delivery**
 - 1 Shelf fixed.
 - Mounting kit.
- **How supplied**
 - In sets.



W	H	WxL	Order No.	UP
482.6	88.1	442 x 280	01.102.731.X.001	1 unit
482.6	88.1	442 x 380	01.102.731.X.002	1 unit



MEC20284

19" Shelf 2 U adjustable

 - For mounting in racks with adjustable 19" installation at front.
- Quick and easy mounting on 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.
- Also for swing frame in the 19" rack and 19" enclosure.
- Depth can be adjusted in increments of 25 mm.

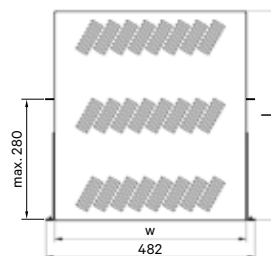

MEC20285

- **Material**
 - Sheet steel 1.5 mm, powder-coated texture.
- **Color**
 - Final digit of order number .1: RAL 7035 light-grey.
 - Final digit of order number .8: RAL 7021 dark-grey.
- **Load rating**
 - 200 N static.
- **Scope of delivery**
 - 1 Shelf adjustable.
 - Mounting kit.
- **How supplied**
 - In sets.

W	H	WxL	Order No.	UP
482.6	88.1	442 x 480	01.102.733.X.003	1 unit



Dimensions in mm:				Conversion:	
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch	
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds	
D = Depth	L = Length	UP = Packaging unit			



MEC20286

19" Drawer Installed on the front

 - Quick and easy mounting from front to 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.
- For storing service documents.

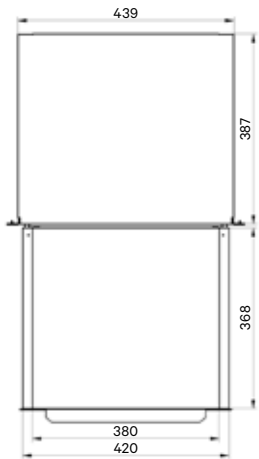

MEC20287

■ **Material / Finish**

- Drawer, sheet steel, powder-coated texture.

■ **Color**

- Final digit of order number .1: RAL 7035, light grey.
- Final digit of order number .8: RAL 7021 dark-grey.

■ **Load rating**

- 150 N static.

■ **Scope of delivery**

- 1 19" drawer with lock, including key.
- 2 Telescopic slides.
- Mounting kit.

■ **How supplied**

- Pre-assembled.


W	H	U	Order No.	UP
482,6	43,6	1	01.102.740.X.001	1 unit
482,6	88,1	2	01.102.740.X.002	1 unit
482,6	132,5	3	01.102.740.X.003	1 unit



MEC20272

19" Writing board 1 U full extension

- With handle.
- Can also be used as shelf.
- Locks in extended position (friction lock).
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.

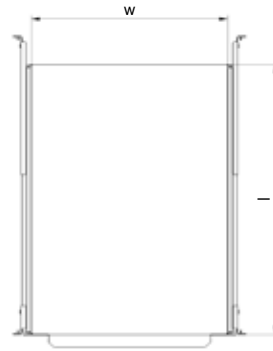

MEC20273

■ **Material / Finish**

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Tableau: Sheet steel 1.0 mm, powder-coated texture.

■ **Color**

- Final digit of order number .1: RAL 7035 light-grey.
- Final digit of order number .8: RAL 7021 dark-grey.

■ **Load rating**

- 500 N static.

■ **Scope of delivery**

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Telescopic slides.
- 1 Tableau with handle.
- Mounting kit.

■ **How supplied**

- Pre-assembled.


d _{insertion depth}	WxL	Order No.	UP
365-565	408 x 360	01.102.705.X.001	1 unit
565-750	408 x 560	01.102.706.X.001	1 unit



MEC20279

19" Drawer with lock

- For mounting in racks with fixed 19" installation at front and rear.
- Full extension.
- With lock.
- Locks in extended position (friction lock).
- Quick separator for tool-less removal and decoupling of drawer.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.

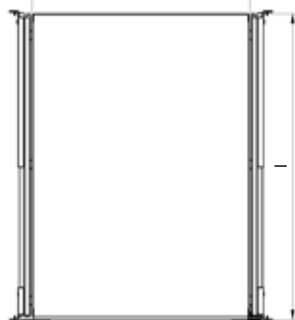

MEC20280

Material / Finish

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Drawer: Sheet steel 1.0 mm, powder-coated texture.

Color

- Final digit of order number .1: RAL 7035 light-grey.
- Final digit of order number .8: RAL 7021 dark-grey.

Load rating

- 400 N static.

Scope of delivery

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Telescopic slides.
- 1 19" drawer with lock, including key.
- Mounting kit.

How supplied

- Pre-assembled.


D	U	WxL	Order No.	UP
565-750	2	408 x 562	01.102.726.X.001	1 unit
565-750	4	408 x 562	01.102.726.X.002	1 unit



MEC20276

19" Keyboard drawer 1 U for 19" keyboard

 - With hand support.
- With cable strain relief.
- Locks in extended position (friction lock).
- Quick separator for tool-less removal and decoupling of drawer.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.



MEC20277

Material / Finish

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Drawer: Sheet steel 1.0 mm, powder-coated texture.
- Front panel: Sheet steel 1.25 mm, powder-coated texture.

Color

- Final digit of order number .1: RAL 7035 light-grey.
- Final digit of order number .8: RAL 7021 dark-grey.

Scope of delivery

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Telescopic slides.
- 1 19" keyboard drawer, 1 U.
- 1 Velcro for securing the keyboard.
- Mounting kit.

How supplied

- Pre-assembled.

d _{insertion depth}	Order No.	UP
565-750	01.102.717.X.001	1 unit

Dimensions in mm:				Conversion:	
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch	
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds	
D = Depth	L = Length	UP = Packaging unit			



MEC20278

19" Keyboard drawer 1 U with extract for PC mouse

- With palm rest.
- Mouse area can be extracted right/left.
- Storage compartment for PC mouse.
- Locks in extended position (friction lock).
- Quick separator for tool-less removal and decoupling of drawer.
- Easy installation from the front of 19" extrusions.
- Integrated latching hooks as mounting aid for mounting hole extrusions.
- Installation on the T-slot extrusions by screwing possible.

■ Dimensions

- Useful shelf space: Dimensions without palm rest 372 x 209 x 24 mm (WxDxH).

■ Material / Finish

- Mounting brackets: Sheet steel 2.0 mm, galvanized.
- Drawer, front panel: Sheet steel 1.25 mm, powder-coated texture.

■ Color

- Final digit of order number .1: RAL 7035 light-grey.
- Final digit of order number .8: RAL 7021 dark-grey.

■ Scope of delivery

- 2 Mounting brackets front left / right.
- 2 Mounting brackets rear left / right.
- 2 Telescopic slides.
- 1 19" keyboard drawer, 1 U.
- 1 Palm rest.
- Mounting kit.

■ How supplied

- In sets.

■ Note

- Keyboard is not included.
- Not compatible with racks, depth 600.

d _{insertion depth}	Order No.	UP
565-750	01.102.722.X.001	1 unit



MEC20027

Document holder

- Self-adhesive; for higher loads use 6 mm holes.
- For DIN A4 documents.

■ Material

- High-impact Polystyrol.

■ Color

- Grey.

■ Scope of delivery

- 1 x document holder.

W	L	T	Bestell-Nr.	VE
264	236	30	05.016.045.0	1 unit



ELM00135

Compact rack lamp

■ Features

- Magnetic mounting.
- Energy-saving lamp.
- Protective contact socket.
- ON/OFF switch.
- Power supply lead 3 m.
- Cover panel.

■ Compliance

- VDE ICE.

■ Protection rating

- IP20.

■ Technical data

- Operating voltage 230 V / 50-60 Hz.
- Lighting: compact fluorescent tube with integrated starter.
- Power consumption: 11 W ≈ 75 W bulb.
- Light intensity: 900 Lm.
- Interference suppression compliant with VDE 0712, IEC 82.
- Socket: 230 VAC / 16A.
- Connections: 3-pole screw clamp, 2.5 mm² with strain relief.

W	H	D	Order No.	UP
65	65	365	01.131.465.9	1 unit



ITC20000

Luminestra LED Rack lighting

- Only for rack type Miracel 2 / DCM W 700, W 800.
- Mounted on the basic frame above the vertical extrusions.
- With LED 4000 Kelvin, 7 watt.
- With on/off rocker switch.
- With 1,8 m power supply cable and EURO plug.
- Complete with mounting material.
- Only with 123 mm front clearance space.

■ Color

- White.

■ Scope of delivery

- 1 x Luminestra rack lamp.
- 2 x mounting brackets.
- 1 x Mounting kit.

W	H	D	Order No.	UP
28	38,4	583	01.131.227.9	1 unit



Dimensions in mm:				Conversion:	
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm	= 0.03937 inch
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg	= 2.2046 pounds
D = Depth	L = Length	UP = Packaging unit			

The right mounting set for every rack type

DCM	MIR2 T-slot	MIR2 Mount. holes	MIR2 Server	MIR2 Swing frame	Smaract T-slot	Smaract Mount. holes	Smaract Server	Double ProRack T-slot	Double ProRack Mount. holes	ConAct	Name	Order No.	UP
	●				●						T-Slot mounting set, M5, wide	05.041.320.9	1 set
		●				●					Mounting set Mount. holes M5/BI 1.5	05.041.321.9	1 set
●			●	●			●				Mounting set Mount. holes M5/BI 2.5	05.041.325.9	1 set 
								●			Mounting set dpr T-slot, M5 narrow	05.041.323.9	1 set
									●		Mounting set dpr mount. holes M5	05.041.322.9	1 set
										●	Mounting Set, ConAct M5	05.041.324.9	1 set

The right mounting set for front panel mounting

Model: Z-form screw

DCM	MIR2 T-slot	MIR2 Mount. holes	MIR2 Server	MIR2 Swing frame	Smaract T-slot	Smaract Mount. holes	Smaract Server	Double ProRack T-slot	Double ProRack Mount. holes	ConAct	Name	Order No.	UP
	●				●						FP mounting set, T-slot M5, wide	05.041.335.9	1 set 
		●				●				●	FP mounting set Mount. holes M5/BI 1.5	05.041.336.9	1 set
●			●	●			●		●		FP mounting set Mount. holes M5/BI 2.5	05.041.337.9	1 set 
								●			FP mounting set, T-slot M5, narrow	05.041.338.9	1 set

The right mounting set for front panel mounting

Model: countersunk screw + rosette

DCM	MIR2 T-slot	MIR2 Mount. holes	MIR2 Server	MIR2 Swing frame	Smaract T-slot	Smaract Mount. holes	Smaract Server	Double ProRack T-slot	Double ProRack Mount. holes	ConAct	Name	Order No.	UP
	●				●						FP mounting set, T-slot M5, wide	05.041.340.9	1 set
		●				●				●	FP mounting set Mount. holes M5/BI 1.5	05.041.341.9	1 set
●			●	●			●		●		FP mounting set Mount. holes M5/BI 2.5	05.041.342.9	1 set
								●			FP mounting set, T-slot M5, narrow	05.041.343.9	1 set

The right accessories for every rack type

DCM	MIR2 T-slot	MIR2 Mount. holes	MIR2 Server	MIR2 Swing frame	Smaract T-slot	Smaract Mount. holes	Smaract Server	Double ProRack T-slot	Double ProRack Mount. holes	ConAct	Name	Order No.	UP
	●				●						Spring nut, M5 wide	01.350.431.9	1 set
								●			Spring nut, M5 narrow	05.041.503.9	1 set
	●				●						Spring nut M6	01.350.405.9	1 set
		●				●				●	Cage nut M5/BI 1.5	05.041.513.7	1 set
●			●	●			●		●		Cage nut M5/BI 2.5	05.041.518.7	1 set
	●				●			●			Oval-head screws, Z-form, M5 x 10	05.041.330.9	1 set
●		●	●	●		●	●		●	●	Oval-head screws, Z-form, M5 x 16	05.041.331.9	1 set
	●				●			●			Countersunk screw M5 x 12 + rosette	05.041.203.9	1 set
●		●	●	●		●	●		●	●	Countersunk screw M5 x 16 + rosette	05.041.290.9	1 set

- assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.



MIRO0114

Mounting tool for cage nuts

- Allows easy clipping of cage nuts on extrusions.

■ **Material**
- Spring steel.

■ **Scope of delivery**
- 1 x mounting tool.

Order No. UP

01.130.985.9 1 unit **P**



MEC20125

T-Slot mounting set, M5, wide for MIR2/Smaract®

- For securing 19" front panels and 19" components.

■ **Scope of delivery**
- 100 x spring nuts, M5 wide.
- 100 x oval-head screws, Z-form, M5 x 10.
- 20 x cage nuts M5 /plate, 1.5 mm.
- 20 x cylinder screws, M5 x 8.

■ **How supplied**
- In sets.

Order No. UP

05.041.320.9 1 set



MEC20126

Mounting set, M5 / plate, 1.5 mm for MIR2/Smaract®

- For securing 19" front panels and 19" components.

■ **Scope of delivery**
- 100 x cage nuts M5 /plate, 1.5 mm.
- 100 x oval-head screws, Z-form, M5 x 16.
- 20 x spring nuts, M5 wide.
- 20 x cylinder screws, M5 x 8.

■ **How supplied**
- In sets.

Order No. UP

05.041.321.9 1 set



MEC20126

Mounting set; mounting holes server extrusion M5 / plate, 2.5 mm for MIR2/DCM/Smaract®

- For securing 19" front panels and 19" components.

■ **Scope of delivery**
- 100 Käfigmuttern M5 / Blech 2.5 mm.
- 100 Linsenschrauben FormZ M5 x 16.
- 20 Federmuttern M5 breit.
- 20 Zylinderschrauben M5 x 8.

■ **How supplied**
- In sets.

Order No. UP

05.041.325.9 1 set **P**



MEC20127

T-slot mounting set, M5, narrow for DoubleProRack®

- For securing 19" front panels and 19" components.

■ **Scope of delivery**
- 100 x spring nuts, M5 narrow.
- 20 x oval-head screws, Z-form, M5 x 10.
- 50 x cylinder screws, M5 x 10.
- 30 x oval-head screws, Z-form, M5 x 8.

■ **How supplied**
- In sets.

Order No. UP

05.041.323.9 1 set



MEC20126

Mounting set; mounting holes M5 for DoubleProRack®

- For securing 19" front panels and 19" components.

■ **Scope of delivery**
- 100 x cage nuts M5 /plate, 2.5 mm.
- 50 x oval-head screws, Z-form, M5 x 16.
- 40 x spring nuts, M5 narrow.
- 40 x cylinder screws, M5 x 10.

■ **How supplied**
- In sets.

Order No. UP

05.041.322.9 1 set

P = assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.

Dimensions in mm:				Conversion:	
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch	
H = Height	d = Insertion depth	(1 U = 44.45 mm)		1 kg = 2.2046 pounds	
D = Depth	L = Length	UP = Packaging unit			



MEC20096

Mounting holes, mounting set, M5 for ConAct®

- For securing 19" front panels and 19" components.

Scope of delivery

- 50 x cage nuts M5 /plate, 1.5 mm.
- 50 x oval-head screws, Z-form, M5 x 16.
- 50 x cylinder screws, M5 x 8.
- 25 x locking nuts, M5.

How supplied

- In sets.

Order No.	UP
05.041.324.9	1 set



MEC20129

Front panel mounting set, T-slot, M5 wide for MIR2/Smaract®

- For securing 19" front panels and 19" components.

Scope of delivery

- **Type 1:**
50 x spring nuts, M5 wide.
50 x oval-head screws, Z-form, M5 x 10.
- **Type 2:**
50 x spring nuts, M5 wide.
50 x countersunk screws, M5 x 12.
50 x rosettes.

How supplied

- In sets.

Model	Order No.	UP
Type 1: Z-form screw	05.041.335.9	1 set
Type 2: screw + rosette	05.041.340.9	1 set



MEC20098

Front panel mounting set for MIR® 2/Smaract®/ConAct®

- For securing 19" front panels and 19" components.
- Mounting holes.

Scope of delivery

- **Type 1:**
50 x cage nuts M5 /plate, 1.5 mm.
50 x oval-head screws, Z-form, M5 x 16.
- **Type 2:**
50 x cage nuts M5 /plate, 1.5 mm.
50 x countersunk screws, M5 x 16.
50 x rosettes.

How supplied

- In sets.

Model	Order No.	UP
Type 1: Z-form screw	05.041.336.9	1 set
Type 2: screw + rosette	05.041.341.9	1 set



MEC20098

Front panel mounting set; mounting holes, M5/plate, 2.5 mm for MIR2/DCM®/Smaract®/DoubleProRack®

- For securing 19" front panels and 19" components.

Scope of delivery

- **Type 1:**
50 x cage nuts M5 /plate, 2.5 mm.
50 x oval-head screws, Z-form, M5 x 16.
- **Type 2:**
50 x cage nuts M5 /plate, 2.5 mm.
50 x countersunk screws, M5 x 16.
50 x rosettes.


How supplied

- In sets.



MEC20097

Model	Order No.	UP
Type 1: Z-form screw	05.041.337.9	1 set
Type 2: Screw + rosette	05.041.342.9	1 set

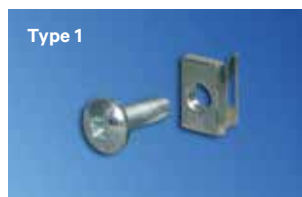

MEC20129

Front panel mounting set, T-slot for DoubleProRack®

- For securing 19" front panels and 19" components.

Scope of delivery

- **Type 1:**
50 x spring nuts, M5 narrow.
50 x oval-head screws, Z-form, M5 x 10.
- **Type 2:**
50 x spring nuts, M5 narrow.
50 x countersunk screws, M5 x 12.
50 x rosettes.

How supplied

- In sets.



MEC20130

Model	Order No.	UP
Type 1: Z-form screw	05.041.338.9	1 set
Type 2: screw + rosette	05.041.343.9	1 set



MEC00060

Spring nut

- To clip on T-slot where required.
- **Type 1:** M5 wide for Miracel 2 / Smaract. T-slot size: 10 x 13 mm.
- **Type 2:** M5 narrow for DoubleProRack. T-slot size: 8 x 13 mm.
- **Type 3:** M6 for Miracel 2 / Smaract. T-slot size: 10 x 13 mm.

■ **Scope of delivery**
- 50 x spring nuts.

■ **How supplied**
- In sets.

Model	Order No.	UP
Type 1: M5 wide	01.350.431.9	1 set
Type 2: M5 narrow	05.041.503.9	1 set
Type 3: M6	01.350.405.9	1 set



MEC20139

Cage nut

- For clipping into extrusions with mounting holes.
- **Type 1:** Plate, 1.5 mm for Miracel 2 / Smaract / ConAct.
- **Type 2:** Plate, 2.5 mm for Miracel 2 Server / Smaract Server / DoubleProRack with 19" mounting holes.

■ **Scope of delivery**
- 50 x cage nuts.

■ **How supplied**
- In sets.

Model	Order No.	UP
M5: Type 1: Plate, 1.5 mm	05.041.513.7	1 set
M5: Type 2: Plate, 2.5 mm	05.041.518.7	1 set
M6: Type 1: Plate, 1.5 mm	05.041.514.7	1 set
M6: Type 2: Plate, 2.5 mm	05.041.519.7	1 set



MEC20140

Oval-head screw

- IEC DIN 967.
- **Scope of delivery**
- 50 x oval-head screws, Z-form.
- **How supplied**
- In sets.

Model	Order No.	UP
M5 x 10	05.041.330.9	1 set
M5 x 16	05.041.331.9	1 set
M6 x 10	05.041.332.9	1 set
M6 x 16	05.041.333.9	1 set



MEC20141

Countersunk screw + rosette

- IEC DIN EN ISO 7047.
- **Scope of delivery**
- 50 x countersunk screws.
- 50 x rosettes.
- **How supplied**
- In sets.

Model	Order No.	UP
M5 x 12	05.041.203.9	1 set
M5 x 16	05.041.290.9	1 set



MEC80020

Oval-head screw self-guiding

- DIN 7500.
- Suitable for system accessories fixed on the inside of the 19" extrusions.
- Suitable for 19" steel and 19" aluminum extrusions.
- Easy screwing.
- **Scope of delivery**
- 50 x oval-head screws, M6x10.
- **How supplied**
- In sets.

Model	Order No.	UP
M6 x 10	05.041.334.9	1 set

assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.

Dimensions in mm:				Conversion:
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch
H = Height	d = Insertion depth	(1U = 44.45 mm)		1 kg = 2.2046 pounds
D = Depth	L = Length	UP = Packaging unit		



MEC20227

Oval-head screw With Phillips head

– IEC DIN EN ISO 7045.

■ **Scope of delivery**
– 1 x set of 50 units.



MEC20228

L	Model	Order No.	UP
8	M 5 no washer	05.041.611.8	1 set
12	M 4 no washer	05.041.609.8	1 set
12	M 5 with washer	05.041.613.8	1 set
16	M 5 with washer	05.041.614.8	1 set
16	M 6 with washer	05.041.616.8	1 set



MEC20226

Cylinder screw With hexagon head

– IEC ISO 4762 (modified).

■ **Scope of delivery**
– 1 x set of 50 units.

L	Model	Order No.	UP
8	M 5	05.041.574.8	1 set
8	M 5 microencapsulated	05.041.575.9	1 set



MEC20225

Tensiloc nut

■ **Material**
– Steel nickel-plated.

■ **Scope of delivery**
– 1 x set of 50 units.

Model	Order No.	UP
M 5	05.041.533.8	1 set



HEI00379

Distribution box

- For mounting trade-standard installation technology DIN rail components, such as fuses, clamps, relays, etc.
- When installed, the mounting level can be pulled out at the front and locked in position, significantly simplifying the wiring of the individual components. Not available for “fixed installation” model. Up on request: Delivered assembled and wired. Further versions and models up on request.
- Installation space for up to 22 pieces of equipment with 18 mm width each.
- Mounting of the TS35 DIN rail on several levels with simple plug-in connection. Not available for “fixed installation” model.
- “Snap-in” mounting of DIN rail components.
- Easy access to the protective grounding and neutral conductor rails from the front.
- Various positioning options available for N and PE rails. Not available for “fixed installation” model.
- Cable entry at the rear via double brush strip (optionally via bushing sockets).
- Cable strain relief on the inside and therefore accessible from the front.
- Labeling strips on the front, above and below the installation space.
- Installation options available for power distribution with 230 V AC, but also in the low-voltage range (e.g. 48 V DC).
- 19" slot-in, 3 U, depth 150 mm.

■ **Material / Finish**
– Panels powder-coated texture, RAL 7035 light-grey.
– Main unit, sheet steel, zinc-passivated.

■ **Scope of delivery**
– 1 x distribution box.
– Including N and PE rails, cable entry, cable strain relief, empty panel covers and grounding set.

■ **How supplied**
– Fully assembled.

W	H	D	U	19"	Model	Order No.	UP
482.6	134	150	3	•	Pull-out	03.013.385.1	1 unit



HEI20282



ELM00137

Door contact switch

- On/off switch, 4 A, 230 V ~.
- Activated by opening and closing door.

Scope of delivery

- 1 x door contact switch (not wired).
- 1 x mounting bracket.
- 1 x Mounting kit.

	Order No.	UP
	01.110.722.9	1 unit
For rack type ConAct	01.110.722.9.001	1 unit




ELM00033

Cable junction box

- For 230 V electrical installation on-site.
- As fixed-location exchange point.
- Quick and easy mounting.

Scope of delivery

- 1 x cable junction box.

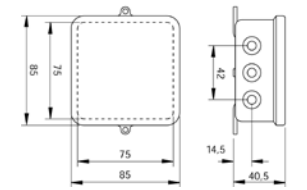

ELM00034

	Order No.	UP
	00.078.720.9	1 unit



ELM00128

Modular terminal box

- For 230V electrical installation on-site.
- With series terminal, 8 x 42.
- Pg 11/16 entry.
- IP 54.

Material

- High-impact, fire-resistant polystyrene.

Scope of delivery

- 1 x modular terminal box.
- 4 pg compression glands, pg11.

	Order No.	UP
	01.117.521.9	1 unit

P = assemble to order (shipped within 5 working days).
Caution: In case of larger orders, delivery times may increase.



ELM00114

1 equipotential bonding bar

- For central grounding of all protective conductors.
- With sealable cover.
- Connection options:
1 x round conductor 8 – 10 mm Ø
1 x flat conductor up to 30 mm wide or round conductor 8 – 10 mm Ø.
- 7 x single or multi-wire conductors up to 16 mm² or fine-wire conductors up to 10 mm².

Material

- Base plate and cover plate, high-impact plastic.
- Brass nickel-plated contact strip.

Scope of delivery

- 1 x equipotential bonding bar.

	Order No.	UP
	01.117.524.3	1 unit



ELM00068

Grounding bar

- For safe grounding or potential equalization of equipments and components.

Material

- Electrolyte copper 9 x 9.

Scope of delivery

- 1 x grounding bar.
- 2 x brackets.
- 1 x Mounting kit.

U	Model	Order No.	UP
24	For DoubleProRack	01.240.546.9	1 unit
21	For DoubleProRack	01.240.545.9	1 unit
18	For DoubleProRack	01.240.544.9	1 unit
15	For DoubleProRack	01.240.543.9	1 unit
45	For Miracel 2 / DCM	01.110.709.9	1 unit
41	For Miracel 2 / DCM	01.110.708.9	1 unit P
12	For Miracel 2 / DCM	01.110.703.9	1 unit



DOP20016

Contact clamp

- Enables safe connection of equipment and components to grounding bar.
- For cables up to 25 mm².

Scope of delivery

- 20 x contact clamps.

	Order No.	UP
	01.110.715.9	20 units P

Dimensions in mm:				Conversion:
W = Width	h = Installation height	U = Standard rack unit	kg = Weight	1 mm = 0.03937 inch
H = Height	d = Insertion depth	(1U = 44.45 mm)		1 kg = 2.2046 pounds
D = Depth	L = Length	UP = Packaging unit		